
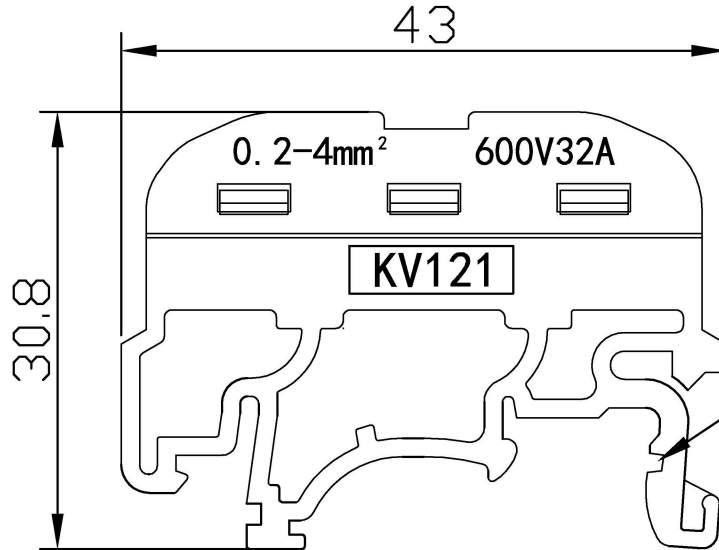


# Specification

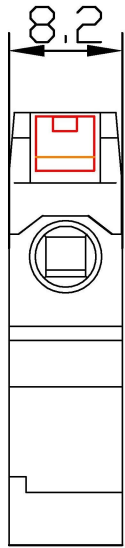

Suitable for TH35-7.5 guide rails

**Specification :**


- 1. Applicable wires : 24-12AWG
- 2. Voltage Rating : 250V/600V
- 3. Current Rating : 32A
- 4. Contact Resistance :  $\leq 0.015\Omega$
- 5. Insulation Resistance :  $\geq 1000M\Omega$

**Material :**

Shell : PA66 /NYLON UL94V-2(0)  
 Liaison piece : Brass ,tin plated  
 Spring buckle: imported 301 stainless steel

Meet Reach 15 tests

Tolerances of dimensions less than 5 ,  $\pm 0.05mm$

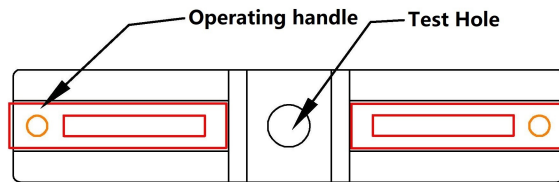

**Belden**

A Change Log	NO.	Change Content	Person in Charge	Change Date	Unit: mm		Product Name	Connector terminal KV121			Date
	1				0.0			Material			
	2				0.000	Approve		Draw	Examine		Weight
	3					Version :					Draw No.

