

Certificate

No. P000586345-07-01-A

Customer:

Belden Wire & Cable B.V.
Edisonstraat 9
5928 Venlo, Netherlands

Category 6A

Test sample(s):

Balanced cable:
Cat. 6A U/UTP AWG23
Part-no.: 10GB24x

Applied standard(s):

ISO/IEC 11801-1 Ed.1.0 (2017-11)
DIN EN 50173-1 (2018-10)
IEC 61156-5 Ed.3.0 (2020-04)

Result(s):

The sample meets the limits of the specified standards and regulations with respect to the parameters indicated above.


Balanced cable, Copper, Category 6A

GHMT Type Approval

The test results which were determined in the course of the measurement refer to the submitted specimen. Any future technical modifications of the verified products are subject to the responsibility of the manufacturer.

This Certificate refers to the comprehensive test report no. P000586345-07-01-A and shall only be applicable in conjunction with the test report. This certificate is valid 24 months after date of testing

Bexbach, 07.05.2026

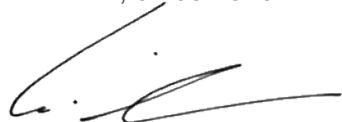

Dirk Wilhelm, engineer
(Chairman of the Managing Board)



GHMT AG

In der Kolling 320
66450 Bexbach / Germany

T: +49 6826 92 28-0
F: +49 6826 92 28-290

info@ghmt.de
www.ghmt.de

**RELIABILITY IN TOTAL
REQUIRES ACCURACY
IN DETAIL.**