


EVM-6P/DCM

The 6-port Dry Contact Input Module allows multiple dry contact sensors to connect to the PDU and provides 12V output up to 200mA for external sensors.

Dimensions


Front Panel View

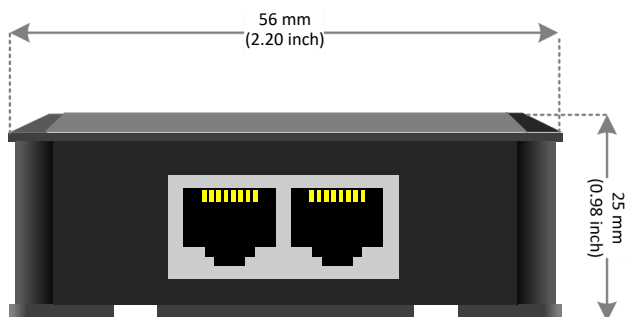


Rear Panel View




Left Panel View

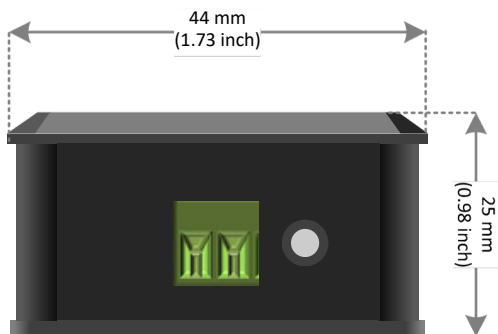

Right Panel View

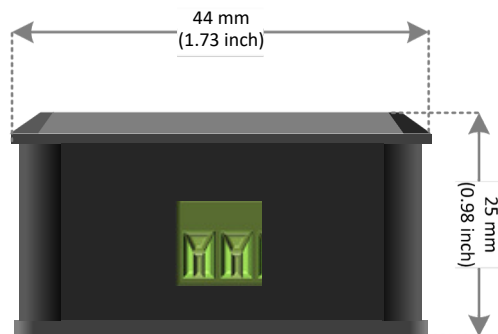

Top Panel View

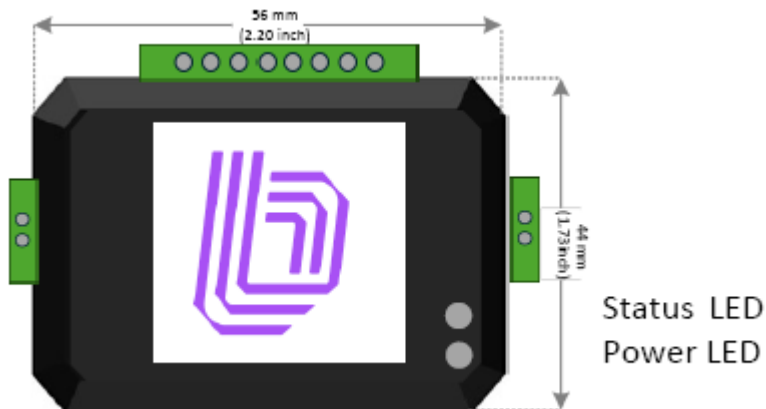

Technical Properties

Maximum Distance from Main Unit	100 m
12V Output Voltage	YES
Current Capacity	200 mA (for sensor supply; external power required if exceeded)
Power Over Sensor Port	YES
External Device Input	YES – 6 Unit
Supported External Devices	YES – Detectors and devices with dry contact output. (Smoke detector, Magnetic Contact etc...)
Supported Units	IP PDU

Operational Properties

Power Supply Voltage	4,5 - 12 VDC
Power Consumption	0,005 - 0,007 A typical 0,006 A 0,0525 - 0,10 W typical 0,072 W
Operational Temperature Range	-25 - +70 °C
Operational Humidity Range	0 - 85 %Rh
Storage Temperature Range	-40 - +85 °C
Storage Humidity Range	0 - 90 %Rh

Physical Properties

Dimensions (H x W x D)	56 x 44 x 25 mm
Color	Black
Weight	60 (± 5%) grams