



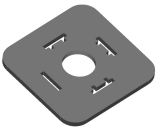

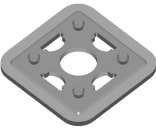






PRODUCT SERIES			GDM	GDME	GDMF	GDMW
						
FLAT GASKET	DESCRIPTION / ORDER NUMBER	MATERIAL / COLOR TEMP RANGE	COMPATIBILITY			
	GDM 3-7 NBR 730801002	NBR / Brown -30° C to +90° C	●	●	●	●
	GDM 3-21 EPDM 731739004	EPDM / Brown -40° C to +125° C	●	●	●	●
	GDM 3-22 FKM 735724002	FKM / Black -15° C to +125° C	●	●	●	●
	GDM 3-17 MPQ 731740002	VQM / Red -40° C to +140° C	●	●	●	●
	PROFILE GASKET					
	GDM 3-16 NBR 731531002	NBR / Black -30° C to +90° C	●		●	
	GDM 3-19 MPQ 731532002	VQM / Red -40° C to +140° C	●		●	
	CAPTIVE GASKET			Compatibility limited to GDM 3G and GDMF Low Profile only		
	GDMF-NBR 735677003	NBR / Black -30° C to +90° C	●		●	
	GDMF-EPDM 735677004	EPDM / Brown -40° C to +125° C	●		●	
	CENTER SCREW					
	GDM 3011-6 732383004	Steel, Phillips Head M3 x 35	●			●
	GDM 3011 RF-1 734363001	SS (316), Phillips Head M3 x 35	●			●
	GDM 3011-18 735507002	Steel, Torx Head M3 x 35	●			●
	GDM 3011-7 Grey 732488002	Steel, Knurled PA M3 x 35	●			●
	GDM 3011-7 Black 732488900	Steel, Knurled PA M3 x 35	●			●
	GDME 3N-11 733974002	Steel, Phillips Head M3 x 40		●		
	GDM 3011-7 Grey 732488002	Steel, Knurled PA M3 x 35		●		