

Product: [0985 656 103](#) 




EtherMATE - Industrial Ethernet double-ended cord set, high-flex, male, M12 to RJ45 straight, 4-pair, 24 AWG, PVC cable, stranded/shielded with teal jacket and orange inserts.

Product Description

EtherMATE - Industrial Ethernet double-ended cord set, high-flex, male, M12 to RJ45 straight, 4-pair, 24 AWG, PVC cable, stranded/shielded with teal jacket and orange inserts.

Technical Drawing

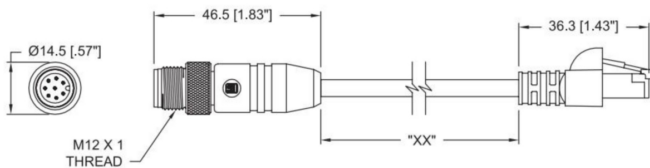

M12	Color	RJ45
6	White/Orange	1
4	Orange	2
1	White/Blue	5
7	Blue	4
5	White/Green	3
8	Green	6
2	White/Brown	7
3	Brown	8
Nut	Shield	Shell

Technical Specifications

Product Description

Brand:	Lumberg Automation
--------	--------------------

Technical Data Side 1

Side 1 Type of Contact/Gender:	pin
Contact Base Material:	RJ45: 50µ" gold in contact area over nickelt plating / M12: Brass, gold over nickel plated
Molded Body Material:	PUR, black
Attachment Plating:	Brass, nickel plated

Cable Data

Cable Type:	103
Cable Number:	656
Cable Diameter D:	7.77 mm nominal
Foil shield:	Aluminum/polypropylene tape, 100% coverage

History

Variants

Item #	Item Description	Cable Length	Color
900005082	0985 656 103/50M		
TJNPI00858	0985 656 103/5M		
900000593	0985 656 103/0.3M	0.3 m	Black
900000594	0985 656 103/0.5M	0.5 m	Black
900000497	0985 656 103/1M	1 m	Black
900000536	0985 656 103/1.5M	1.5 m	Black
900000461	0985 656 103/2M	2 m	Black
900000498	0985 656 103/3M	3 m	Black
900000537	0985 656 103/4M	4 m	Black
900000499	0985 656 103/5M	5 m	Black
900000595	0985 656 103/10M	10 m	Black
900001551	0985 656 103/15M	15 m	Black
900002080	0985 656 103/20M	20 m	Black

© 2026 Belden, Inc

All Rights Reserved.

Although Belden makes every reasonable effort to ensure their accuracy at the time of this publication, information and specifications described here in are subject to error or omission and to change without notice, and the listing of such information and specifications does not ensure product availability.

Belden provides the information and specifications herein on an "ASIS" basis, with no representations or warranties, whether express, statutory or implied. In no event will Belden be liable for any damages (including consequential, indirect, incidental, special, punitive, or exemplary damages) whatsoever, even if Belden has been advised of the possibility of such damages, whether in an action under contract, negligence or any other theory, arising out of or in connection with the use, or inability to use, the information or specifications described herein.

All sales of Belden products are subject to Belden's standard terms and conditions of sale.

Belden believes this product to be in compliance with all applicable environmental programs as listed in the data sheet. The information provided is correct to the best of Belden's knowledge, information and belief at the date of its publication. This information is designed only as a general guide for the safe handling, storage, and any other operation of the product itself or the one that it becomes a part of. The Product Disclosure is not to be considered a warranty or quality specification. Regulatory information is for guidance purposes only. Product users are responsible for determining the applicability of legislation and regulations based on their individual usage of the product.