



**Product:** [Cabinet Series Bottom Cover](#)


**XH Cabinet Series Bottom Cover Options**



**Product Description**

XH Cabinet Series Bottom Cover Options. Bottom cover options are compatible for all XHS/XHSS/XHM/XHMS/XHSN Series Cabinets.

**Technical Drawing**

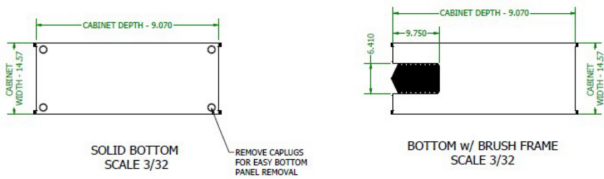

**Technical Specifications**

**Application**

Product Overview:	These individual component ordering options are available as an ala carte option for customers that have existing XH Series Belden Cabinets and would like to replace an item, or want to add an additional item. These component selections are not meant to serve as an individual item selection to create a complete cabinet. If you would like to configure a cabinet for a BOM, please go to the cabinet configurator section of the online catalog that is titled "Need a custom configured product?" or do a search in the search bar for the cabinet series you are looking for to see the selection of compatible items available.
Features:	Bottom brush panel can be rotated 180 degrees for choice of front or rear brush entry
Environmental Space:	Indoor

**Environmental and Overall Characteristics**

Finish:	Medium Texture Powder Coat
Material:	Steel

**Related Part Numbers**

Packaging:	If ordered with a cabinet, bottom panel will be installed with brush in the rear. If ordered separately, product will be packaged and shipped.
------------	--

**Variants**

Cabinet Frame Width	Cabinet Frame Depth	Panel Color	Ordering Part #	Bottom Cable Access
24.0 in	30.0 in	Black	H2430BCS01	Solid - No Openings
24.0 in	36.0 in	Black	H2436BCS01	Solid - No Openings
24.0 in	42.0 in	Black	H2442BCS01	Solid - No Openings
24.0 in	48.0 in	Black	H2448BCS01	Solid - No Openings
24.0 in	30.0 in	Black	H2430BCWB01	Solid with Brush
24.0 in	36.0 in	Black	H2436BCWB01	Solid with Brush
24.0 in	42.0 in	Black	H2442BCWB01	Solid with Brush
24.0 in	48.0 in	Black	H2448BCWB01	Solid with Brush
30.0 in	30.0 in	Black	H3030BCS01	Solid - No Openings
30.0 in	36.0 in	Black	H3036BCS01	Solid - No Openings
30.0 in	42.0 in	Black	H3042BCS01	Solid - No Openings
30.0 in	48.0 in	Black	H3048BCS01	Solid - No Openings
30.0 in	30.0 in	Black	H3030BCWB01	Solid with Brush
30.0 in	36.0 in	Black	H3036BCWB01	Solid with Brush
30.0 in	42.0 in	Black	H3042BCWB01	Solid with Brush

30.0 in	48.0 in	Black	H3048BCWB01	Solid with Brush
40.0 in	42.0 in	Black	H4042BCS01	Solid - No Openings
40.0 in	48.0 in	Black	H4048BCS01	Solid - No Openings
40.0 in	42.0 in	Black	H4042BCWB01	Solid with Brush
40.0 in	48.0 in	Black	H4048BCWB01	Solid with Brush
24.0 in	30.0 in	White	H2430BCS02	Solid - No Openings
24.0 in	36.0 in	White	H2436BCS02	Solid - No Openings
24.0 in	42.0 in	White	H2442BCS02	Solid - No Openings
24.0 in	48.0 in	White	H2448BCS02	Solid - No Openings
24.0 in	30.0 in	White	H2430BCWB02	Solid with Brush
24.0 in	36.0 in	White	H2436BCWB02	Solid with Brush
24.0 in	42.0 in	White	H2442BCWB02	Solid with Brush
24.0 in	48.0 in	White	H2448BCWB02	Solid with Brush
30.0 in	30.0 in	White	H3030BCS02	Solid - No Openings
30.0 in	36.0 in	White	H3036BCS02	Solid - No Openings
30.0 in	42.0 in	White	H3042BCS02	Solid - No Openings
30.0 in	48.0 in	White	H3048BCS02	Solid - No Openings
30.0 in	30.0 in	White	H3030BCWB02	Solid with Brush
30.0 in	36.0 in	White	H3036BCWB02	Solid with Brush
30.0 in	42.0 in	White	H3042BCWB02	Solid with Brush
30.0 in	48.0 in	White	H3048BCWB02	Solid with Brush
40.0 in	42.0 in	White	H4042BCS02	Solid - No Openings
40.0 in	48.0 in	White	H4048BCS02	Solid - No Openings
40.0 in	42.0 in	White	H4042BCWB02	Solid with Brush
40.0 in	48.0 in	White	H4048BCWB02	Solid with Brush

Update and Revision:	Revision Number: 0.55 Revision Date: 05-31-2024
----------------------	---

© 2024 Belden, Inc

All Rights Reserved.

Although Belden makes every reasonable effort to ensure their accuracy at the time of this publication, information and specifications described here in are subject to error or omission and to change without notice, and the listing of such information and specifications does not ensure product availability.

Belden provides the information and specifications herein on an "ASIS" basis, with no representations or warranties, whether express, statutory or implied. In no event will Belden be liable for any damages (including consequential, indirect, incidental, special, punitive, or exemplary damages) whatsoever, even if Belden has been advised of the possibility of such damages, whether in an action under contract, negligence or any other theory, arising out of or in connection with the use, or inability to use, the information or specifications described herein.

All sales of Belden products are subject to Belden's standard terms and conditions of sale.

Belden believes this product to be in compliance with all applicable environmental programs as listed in the data sheet. The information provided is correct to the best of Belden's knowledge, information and belief at the date of its publication. This information is designed only as a general guide for the safe handling, storage, and any other operation of the product itself or the one that it becomes a part of. The Product Disclosure is not to be considered a warranty or quality specification. Regulatory information is for guidance purposes only. Product users are responsible for determining the applicability of legislation and regulations based on their individual usage of the product.