




Product: [Cabinet Series Vented w/Polycarbonate Door Options](#)

XH Cabinet Series Vented w/Polycarbonate Door Options

Product Description

XH Cabinet Series Vented w/Polycarbonate Door Options

Technical Drawing

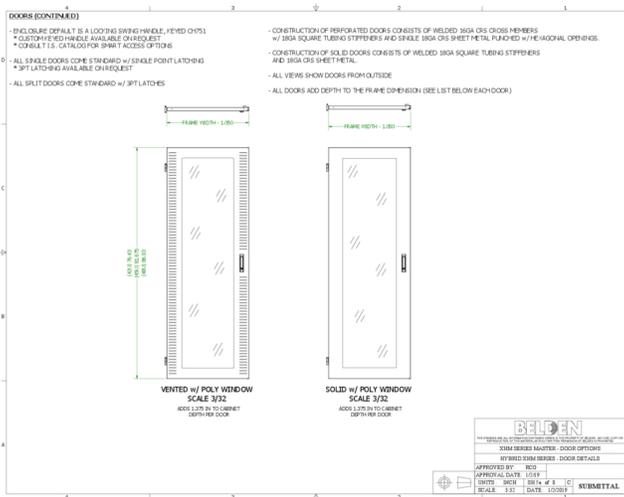

Technical Specifications

Application

Product Overview:	These individual component ordering options are available as an ala carte option for customers that have existing XH Series Belden Cabinets and would like to replace an item, or want to add an additional item. These component selections are not meant to serve as an individual item selection to create a complete cabinet. If you would like to configure a cabinet for a BOM, please go to the cabinet configurator section of the online catalog that is titled "Need a custom configured product?" or do a search in the search bar for the cabinet series you are looking for to see the selection of compatible items available.
Features:	Vented w/Polycarbonate Doors are currently only available on the XHM & XHS Series Cabinets, Belden offers an array of door options that are available with the XH Cabinet Series., All single doors come equipped with single point latching with a Locking Swing Handle keyed CH751.
Environmental Space:	Indoor

Environmental and Overall Characteristics

Finish:	Medium Texture Powder Coat
Material:	Steel with Polycarbonate

Related Part Numbers

Packaging:	If ordered with a cabinet, door will be installed. If ordered separately, product will be packaged and shipped. *Note a crate packing charge will apply to protect doors in transit
------------	---

Variants

Cabinet Frame Height	Cabinet Frame Width	Color	Application	Ordering Part #
42U	24.0 in	Black	XHM Series	H4224VPLYD01
42U	30.0 in	Black	XHM Series XHS Series	H4230VPLYD01
45U	24.0 in	Black	XHM Series	H4524VPLYD01
45U	30.0 in	Black	XHM Series XHS Series	H4530VPLYD01

48U	24.0 in	Black	XHM Series	H4824VPLYD01
48U	30.0 in	Black	XHM Series XHS Series	H4830VPLYD01
42U	24.0 in	White	XHM Series	H4224VPLYD02
42U	30.0 in	White	XHM Series XHS Series	H4230VPLYD02
45U	24.0 in	White	XHM Series	H4524VPLYD02
45U	30.0 in	White	XHM Series XHS Series	H4530VPLYD02
48U	24.0 in	White	XHM Series	H4824VPLYD02
48U	30.0 in	White	XHM Series XHS Series	H4830VPLYD02

Update and Revision:	Revision Number: 0.51 Revision Date: 05-31-2024
----------------------	---

© 2024 Belden, Inc

All Rights Reserved.

Although Belden makes every reasonable effort to ensure their accuracy at the time of this publication, information and specifications described here in are subject to error or omission and to change without notice, and the listing of such information and specifications does not ensure product availability.

Belden provides the information and specifications herein on an "ASIS" basis, with no representations or warranties, whether express, statutory or implied. In no event will Belden be liable for any damages (including consequential, indirect, incidental, special, punitive, or exemplary damages) whatsoever, even if Belden has been advised of the possibility of such damages, whether in an action under contract, negligence or any other theory, arising out of or in connection with the use, or inability to use, the information or specifications described herein.

All sales of Belden products are subject to Belden's standard terms and conditions of sale.

Belden believes this product to be in compliance with all applicable environmental programs as listed in the data sheet. The information provided is correct to the best of Belden's knowledge, information and belief at the date of its publication. This information is designed only as a general guide for the safe handling, storage, and any other operation of the product itself or the one that it becomes a part of. The Product Disclosure is not to be considered a warranty or quality specification. Regulatory information is for guidance purposes only. Product users are responsible for determining the applicability of legislation and regulations based on their individual usage of the product.